



CUSTOMER TERMINAL	RoHS	LEAD(Pb)-FREE
Sn96%, Ag4%	Yes	Yes

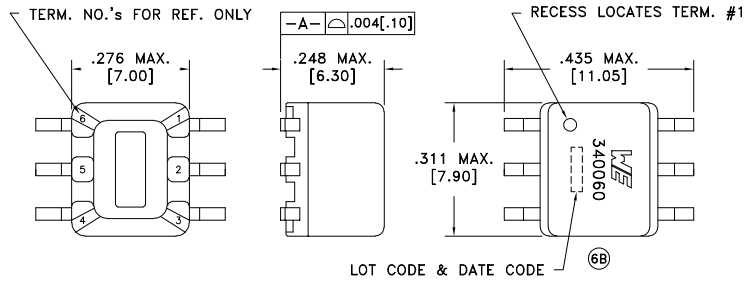

ELECTRICAL SPECIFICATIONS @ 25°C unless otherwise noted:

PARAMETER	TEST CONDITIONS	VALUE
D.C. RESISTANCE	1-6 @20°C	2.22 ohms max.
D.C. RESISTANCE	3-4 @20°C	2.22 ohms max.
INDUCTANCE	1-6 100kHz, 10mVAC, Ls	1.7mH min.
LEAKAGE INDUCTANCE	1-6 tie(3+4), 100kHz, 10mVAC, Ls	8uH max.
DIELECTRIC	1-6 -	1500VDC, 1 minute
DIELECTRIC	3-4 -	1500VDC, 1 minute
URNS RATIO	(1-6):(3-4)	1:1, ±2%

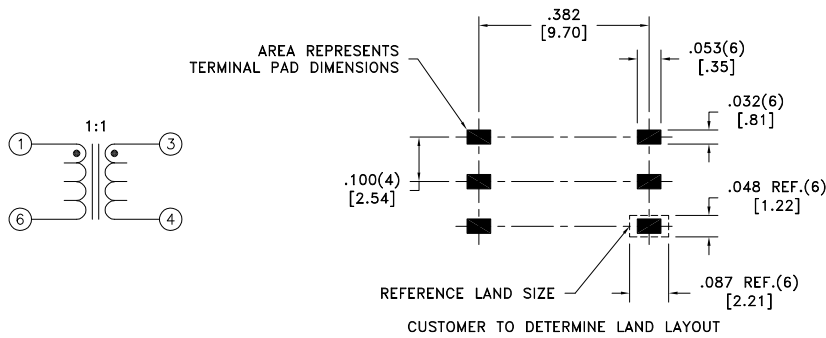

REV.	DATE	Packaging Specifications	CONVENTION PLACEMENT
6B	6/19	Method: Tape & Reel PKG-0743 www.we-online.com/midcom	
6A	11/10	SEE REVISION SHEET FOR REVISION LEVEL	

Tolerances unless otherwise specified:
 Angles: ±1° Decimals: ±.005 [.13]
 Fractions: ±1/64 Footprint: ±.005 [.13]

This drawing is dual dimensioned. Dimensions in brackets are in millimeters.

DRAWING TITLE
TRANSFORMER

eiSos p/n: 750340060

PART NO.
750340060

SPECIFICATION SHEET 1 OF 1

