



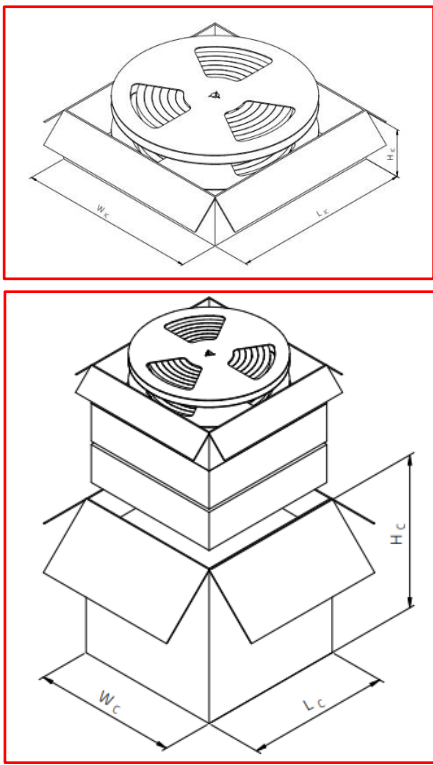
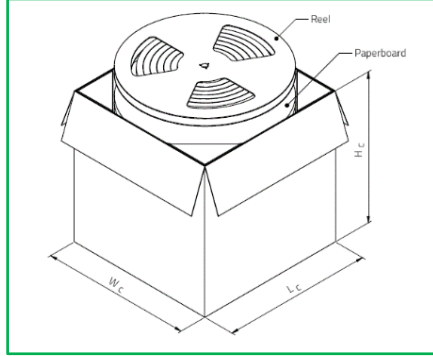


Product / Process Change Notification (PCN)																															
<input type="checkbox"/> Major Change <input checked="" type="checkbox"/> Minor Change																															
PCN Number: PCN_IndXHMI_20241026 Affected Series: WE-XHMI Affected Order Codes: Please refer to table 1 PCN Date: 2024-07-26 (YYYY-MM-DD) Effective Date: 2024-10-26 (YYYY-MM-DD)	Change Category: <input type="checkbox"/> Equipment/Location <input checked="" type="checkbox"/> General Data <input type="checkbox"/> Material <input type="checkbox"/> Process <input type="checkbox"/> Product Design <input checked="" type="checkbox"/> Shipping/Packaging <input type="checkbox"/> Supplier <input type="checkbox"/> Software																														
Contact: Product Management Phone: +49 (0) 7942 - 945 5001 Fax: +49 (0) 7942 - 945 5179 E-Mail: pcn.eisos@we-online.com	Datasheet Change: <input checked="" type="checkbox"/> Yes <input type="checkbox"/> No Attachment: <input type="checkbox"/> Yes <input checked="" type="checkbox"/> No																														
Description of Change: <p>Due to packaging optimizations, Würth Elektronik eiSos will change the product's packing method. Würth Elektronik eiSos will ensure some datasheet corrections for the product series WE-XHMI with sizes and order codes indicated in table 1.</p> <p>There will be no change in form, fit, function, quality, or reliability of the product.</p> <p>The new revision of the affected order codes will be sent out after the previous revision is out of stock (according to FIFO - first-in, first-out).</p>																															
Details of Change: <div style="text-align: center; margin: 10px 0;">Table 1. Affected Order Codes</div> <table border="1" style="width: 100%; border-collapse: collapse; margin: 0 auto;"> <thead> <tr> <th colspan="5" style="text-align: left; padding: 2px;">a. Order codes for size 4020:</th> </tr> </thead> <tbody> <tr> <td style="width: 20%; padding: 2px;">744393230022</td> <td style="width: 20%; padding: 2px;">744393230047</td> <td style="width: 20%; padding: 2px;">744393230056</td> <td style="width: 20%; padding: 2px;">744393230068</td> <td style="width: 20%; padding: 2px;">744393230082</td> </tr> <tr> <td style="padding: 2px;">74439323010</td> <td style="padding: 2px;">74439323012</td> <td style="padding: 2px;">74439323015</td> <td style="padding: 2px;">74439323022</td> <td style="padding: 2px;"></td> </tr> <tr> <th colspan="5" style="text-align: left; padding: 2px;">b. Order codes for size 4030:</th> </tr> <tr> <td style="padding: 2px;">744393240047</td> <td style="padding: 2px;">744393240064</td> <td style="padding: 2px;">744393240090</td> <td style="padding: 2px;">74439324010</td> <td style="padding: 2px;">74439324012</td> </tr> <tr> <td style="padding: 2px;">74439324015</td> <td style="padding: 2px;">74439324022</td> <td style="padding: 2px;">74439324033</td> <td style="padding: 2px;">74439324047</td> <td style="padding: 2px;"></td> </tr> </tbody> </table>		a. Order codes for size 4020:					744393230022	744393230047	744393230056	744393230068	744393230082	74439323010	74439323012	74439323015	74439323022		b. Order codes for size 4030:					744393240047	744393240064	744393240090	74439324010	74439324012	74439324015	74439324022	74439324033	74439324047	
a. Order codes for size 4020:																															
744393230022	744393230047	744393230056	744393230068	744393230082																											
74439323010	74439323012	74439323015	74439323022																												
b. Order codes for size 4030:																															
744393240047	744393240064	744393240090	74439324010	74439324012																											
74439324015	74439324022	74439324033	74439324047																												



c. Order codes for size 4040:				
74439325033	74439325047	74439325056	74439325068	
d. Order codes for size 5020:				
744393330016	744393330033	744393330056	744393330068	74439333010
74439333012				
e. Order codes for size 5030:				
744393340033	744393340056	744393340068	74439334010	74439334012
74439334015	74439334022	74439334033	74439334047	
f. Order codes for size 5050:				
744393305056	744393305068	744393305082	744393305100	744393305150
744393305220				
g. Order codes for size 6030:				
744393440015	744393440018	744393440033	744393440056	74439344010
74439344012	74439344022	74439344033	74439344047	
h. Order codes for size 6060:				
74439346010	74439346012	74439346015	74439346018	74439346022
74439346033	74439346047	74439346056	74439346068	74439346082
74439346100	74439346150			
i. Order codes for size 7030:				
74439384010	74439384012	74439384015	74439384022	74439384033
74439384047				
j. Order codes for size 7070:				
74439387033	74439387047	74439387056	74439387068	74439387082
74439387100				
k. Order codes for size 8080:				
744393580068	74439358010	74439358015	74439358022	74439358047
74439358068	74439358100	74439358150		
l. Order codes for size 1090:				
74439369015	74439369022	74439369033	74439369047	74439369056
74439369068	74439369082	74439369100	74439369150	
m. Order codes for size 1510:				
74439370047	74439370068	74439370082	74439370100	74439370150
74439370220	74439370330			

1. To reduce the amount of packaging waste in the product series WE-XHMI, with sizes and order codes indicated in table 1, the inner boxes will be omitted. No plastic filler will be used, and every reel will be stacked and separated by paperboard. The outer box dimension, reel quantity (pcs.), and box quantity (pcs.) will be updated accordingly. Additional details of the changes can be found in the table below:

Table 2. Packaging Changes of affected Order Codes

	Before Change	After Change
Datasheet packing drawings		
Overview of inner packing change		



Packaging specifications for size 4020 (Table 1 section a)	L _c (mm)	355,00	L _c (mm)	360,00
	W _c (mm)	355,00	W _c (mm)	360,00
	H _c (mm)	385,00	H _c (mm)	270,00
	Outer Box Qty.(pcs.)	24000	Outer Box Qty.(pcs.)	24000
Packaging specifications for size 4030 (Table 1 section b)	L _c (mm)	355,00	L _c (mm)	360,00
	W _c (mm)	355,00	W _c (mm)	360,00
	H _c (mm)	385,00	H _c (mm)	270,00
	Outer Box Qty.(pcs.)	24000	Outer Box Qty.(pcs.)	24000
Packaging specifications for size 4040 (Table 1 section c)	L _c (mm)	355,00	L _c (mm)	360,00
	W _c (mm)	355,00	W _c (mm)	360,00
	H _c (mm)	385,00	H _c (mm)	270,00
	Outer Box Qty.(pcs.)	18000	Outer Box Qty.(pcs.)	18000
Packaging specifications for size 5020 (Table 1 section d)	L _c (mm)	355,00	L _c (mm)	360,00
	W _c (mm)	355,00	W _c (mm)	360,00
	H _c (mm)	385,00	H _c (mm)	240,00
	Outer Box Qty.(pcs.)	18000	Outer Box Qty.(pcs.)	18000
Packaging specifications for size 5030 (Table 1 section e)	L _c (mm)	355,00	L _c (mm)	360,00
	W _c (mm)	355,00	W _c (mm)	360,00
	H _c (mm)	385,00	H _c (mm)	240,00
	Outer Box Qty.(pcs.)	13500	Outer Box Qty.(pcs.)	13500
Packaging specifications for size 5050 (Table 1 section f)	L _c (mm)	355,00	L _c (mm)	360,00
	W _c (mm)	355,00	W _c (mm)	360,00
	H _c (mm)	385,00	H _c (mm)	240,00
	Outer Box Qty.(pcs.)	9000	Outer Box Qty.(pcs.)	9000



Packaging specifications for size 6030 (Table 1 section g)	<table border="1"> <tr><td>L_c (mm)</td><td>355,00</td></tr> <tr><td>W_c (mm)</td><td>355,00</td></tr> <tr><td>H_c (mm)</td><td>385,00</td></tr> <tr><td>Outer Box Qty.(pcs.)</td><td>9000</td></tr> </table>	L _c (mm)	355,00	W _c (mm)	355,00	H _c (mm)	385,00	Outer Box Qty.(pcs.)	9000	<table border="1"> <tr><td>L_c (mm)</td><td>360,00</td></tr> <tr><td>W_c (mm)</td><td>360,00</td></tr> <tr><td>H_c (mm)</td><td>240,00</td></tr> <tr><td>Outer Box Qty.(pcs.)</td><td>9000</td></tr> </table>	L _c (mm)	360,00	W _c (mm)	360,00	H _c (mm)	240,00	Outer Box Qty.(pcs.)	9000
L _c (mm)	355,00																	
W _c (mm)	355,00																	
H _c (mm)	385,00																	
Outer Box Qty.(pcs.)	9000																	
L _c (mm)	360,00																	
W _c (mm)	360,00																	
H _c (mm)	240,00																	
Outer Box Qty.(pcs.)	9000																	
Packaging specifications for size 6060 (Table 1 section h)	<table border="1"> <tr><td>L_c (mm)</td><td>355,00</td></tr> <tr><td>W_c (mm)</td><td>355,00</td></tr> <tr><td>H_c (mm)</td><td>385,00</td></tr> <tr><td>Outer Box Qty.(pcs.)</td><td>6300</td></tr> </table>	L _c (mm)	355,00	W _c (mm)	355,00	H _c (mm)	385,00	Outer Box Qty.(pcs.)	6300	<table border="1"> <tr><td>L_c (mm)</td><td>360,00</td></tr> <tr><td>W_c (mm)</td><td>360,00</td></tr> <tr><td>H_c (mm)</td><td>240,00</td></tr> <tr><td>Outer Box Qty.(pcs.)</td><td>6300</td></tr> </table>	L _c (mm)	360,00	W _c (mm)	360,00	H _c (mm)	240,00	Outer Box Qty.(pcs.)	6300
L _c (mm)	355,00																	
W _c (mm)	355,00																	
H _c (mm)	385,00																	
Outer Box Qty.(pcs.)	6300																	
L _c (mm)	360,00																	
W _c (mm)	360,00																	
H _c (mm)	240,00																	
Outer Box Qty.(pcs.)	6300																	
Packaging specifications for size 7030 (Table 1 section i)	<table border="1"> <tr><td>L_c (mm)</td><td>355,00</td></tr> <tr><td>W_c (mm)</td><td>355,00</td></tr> <tr><td>H_c (mm)</td><td>385,00</td></tr> <tr><td>Outer Box Qty.(pcs.)</td><td>9000</td></tr> </table>	L _c (mm)	355,00	W _c (mm)	355,00	H _c (mm)	385,00	Outer Box Qty.(pcs.)	9000	<table border="1"> <tr><td>L_c (mm)</td><td>360,00</td></tr> <tr><td>W_c (mm)</td><td>360,00</td></tr> <tr><td>H_c (mm)</td><td>240,00</td></tr> <tr><td>Outer Box Qty.(pcs.)</td><td>9000</td></tr> </table>	L _c (mm)	360,00	W _c (mm)	360,00	H _c (mm)	240,00	Outer Box Qty.(pcs.)	9000
L _c (mm)	355,00																	
W _c (mm)	355,00																	
H _c (mm)	385,00																	
Outer Box Qty.(pcs.)	9000																	
L _c (mm)	360,00																	
W _c (mm)	360,00																	
H _c (mm)	240,00																	
Outer Box Qty.(pcs.)	9000																	
Packaging specifications for size 7070 (Table 1 section j)	<table border="1"> <tr><td>L_c (mm)</td><td>355,00</td></tr> <tr><td>W_c (mm)</td><td>355,00</td></tr> <tr><td>H_c (mm)</td><td>385,00</td></tr> <tr><td>Outer Box Qty.(pcs.)</td><td>3600</td></tr> </table>	L _c (mm)	355,00	W _c (mm)	355,00	H _c (mm)	385,00	Outer Box Qty.(pcs.)	3600	<table border="1"> <tr><td>L_c (mm)</td><td>360,00</td></tr> <tr><td>W_c (mm)</td><td>360,00</td></tr> <tr><td>H_c (mm)</td><td>240,00</td></tr> <tr><td>Outer Box Qty.(pcs.)</td><td>3600</td></tr> </table>	L _c (mm)	360,00	W _c (mm)	360,00	H _c (mm)	240,00	Outer Box Qty.(pcs.)	3600
L _c (mm)	355,00																	
W _c (mm)	355,00																	
H _c (mm)	385,00																	
Outer Box Qty.(pcs.)	3600																	
L _c (mm)	360,00																	
W _c (mm)	360,00																	
H _c (mm)	240,00																	
Outer Box Qty.(pcs.)	3600																	
Packaging specifications for size 8080 (Table 1 section k)	<table border="1"> <tr><td>L_c (mm)</td><td>355,00</td></tr> <tr><td>W_c (mm)</td><td>355,00</td></tr> <tr><td>H_c (mm)</td><td>385,00</td></tr> <tr><td>Outer Box Qty.(pcs.)</td><td>3000</td></tr> </table>	L _c (mm)	355,00	W _c (mm)	355,00	H _c (mm)	385,00	Outer Box Qty.(pcs.)	3000	<table border="1"> <tr><td>L_c (mm)</td><td>360,00</td></tr> <tr><td>W_c (mm)</td><td>360,00</td></tr> <tr><td>H_c (mm)</td><td>240,00</td></tr> <tr><td>Outer Box Qty.(pcs.)</td><td>3000</td></tr> </table>	L _c (mm)	360,00	W _c (mm)	360,00	H _c (mm)	240,00	Outer Box Qty.(pcs.)	3000
L _c (mm)	355,00																	
W _c (mm)	355,00																	
H _c (mm)	385,00																	
Outer Box Qty.(pcs.)	3000																	
L _c (mm)	360,00																	
W _c (mm)	360,00																	
H _c (mm)	240,00																	
Outer Box Qty.(pcs.)	3000																	
Packaging specifications for size 1090 (Table 1 section l)	<table border="1"> <tr><td>L_c (mm)</td><td>355,00</td></tr> <tr><td>W_c (mm)</td><td>355,00</td></tr> <tr><td>H_c (mm)</td><td>385,00</td></tr> <tr><td>Outer Box Qty.(pcs.)</td><td>1800</td></tr> </table>	L _c (mm)	355,00	W _c (mm)	355,00	H _c (mm)	385,00	Outer Box Qty.(pcs.)	1800	<table border="1"> <tr><td>L_c (mm)</td><td>360,00</td></tr> <tr><td>W_c (mm)</td><td>360,00</td></tr> <tr><td>H_c (mm)</td><td>240,00</td></tr> <tr><td>Outer Box Qty.(pcs.)</td><td>1800</td></tr> </table>	L _c (mm)	360,00	W _c (mm)	360,00	H _c (mm)	240,00	Outer Box Qty.(pcs.)	1800
L _c (mm)	355,00																	
W _c (mm)	355,00																	
H _c (mm)	385,00																	
Outer Box Qty.(pcs.)	1800																	
L _c (mm)	360,00																	
W _c (mm)	360,00																	
H _c (mm)	240,00																	
Outer Box Qty.(pcs.)	1800																	



Packaging specifications for size 1510 (Table 1 section m)	L _c (mm)	355,00	L _c (mm)	360,00
	W _c (mm)	355,00	W _c (mm)	360,00
	H _c (mm)	385,00	H _c (mm)	270,00
	Outer Box Qty.(pcs.)	900	Outer Box Qty.(pcs.)	900
	Reliability / Qualification of Change:			
There will be no change of the product, therefore no additional reliability or qualification testing was performed.				